




YGHP34C34TN Figure 6 Compression Grounding Connector

By Burndy
Catalog # YGHP34C34TN

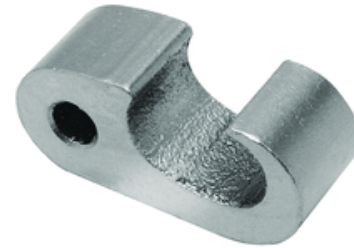

Tin plated Cu Compression Ground Rod Connector, 250- 500 kcmil , 5/8" to 3/4" Rod, 5/8" to 3/4" Rebar (Run) to 350- 500 kcmil (Tap).

General

Connector Type	Tap
Die Index	1011
Material	Copper
Oxide Inhibitor Type	Penetrox E
Physical Attribute - Number of Crimps Required	3
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYTAP™
Type	Taps
UPC	781810527290
UPC 12 Digit	7818105272900

Conductor Related

Conductor - Copper Str Run	250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Run Range	250 kcmil-500 kcmil
Conductor - Copper Str Tap	350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Tap Range	350 kcmil-500 kcmil
Conductor - Rebar Run	5 ;6
Conductor - Rebar Run Range	5 kcmil-6 kcmil
Conductor - Rod Run	5/8 in;3/4 in
Conductor - Rod Run Range	5/8 in-3/4 in

Certifications and Compliance

Certification - CSA Approved	Yes
Industry Standard(s)	Direct Burial
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	5920

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sd082473-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YGHP34C34TN-SPEC-EN | REV 8/2023