




YGHR34C58 Figure 8 Compression Ground Rod Connector

By Burndy
Catalog # YGHR34C58

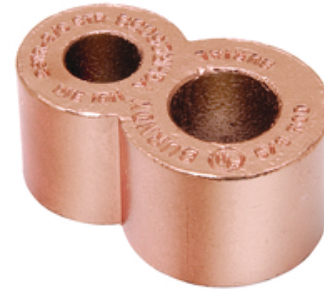

HYTAIL™ Ground Rod Figure 8 Compression Tap Connector.

General

Connector Type	Tap
Die Index	998;1012
Material	Copper
Oxide Inhibitor Type	Penetrox E
Physical Attribute - Number of Crimps Required	1
Plated	N
Plating Type	Unplated
Precrimp Die	UPRECRIMP58
Prefilled Oxide Inhibitor	Y
Trade Name	HYTAIL™
Type	Taps
UPC	781810220771
UPC 12 Digit	7818102207711

Dimensions

Dimension - B Length fraction	22/25 in
Dimension - B Length inch	0.88 in
Dimension - Ground Rod Size	5/8
Dimension - Height fraction	2-7/50 in
Dimension - Height inch	2.14 in
Dimension - L Length Overall mm	22 mm
Dimension - Length Overall inch	0.88 in

Conductor Related

Conductor - Copper Str Size	300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Size Range	300 kcmil-500 kcmil
Conductor - Rod Size	5/8 in
Conductor - Rod Size Range	5/8 in
Conductor Type	<ul style="list-style-type: none">• CU C Str-Size A• Rod-Size B

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none">• UL467• IEEE 837
Standards - Industry Standards Met	<ul style="list-style-type: none">• UL467• IEEE 837
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	15
Pallet Quantity	4640

Product Assets

[3D Models - YGHR34C58_MODEL-STEP](#)
[3D Models - YGHR34C58_MODEL-PDF](#)
[3D Models - YGHR34C58_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sd..088266-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YGHR34C58-SPEC-EN | REV 8/2023

