




YGIBW2810002N Structural Steel Compression Grounding Connector

By Burndy
Catalog # [YGIBW2810002N](#)

I-Beam Connector W/ Wide Flange Beams For Cu Cable, # 2-4/0 AWG.

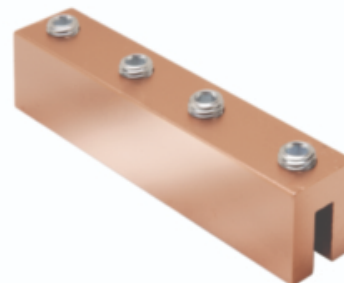

General

Catalog Number	YGIBW2810002N
Connector Type	Tap
Material	Copper
Plated	N
Plating Type	Unplated
Trade Name	GROUNDLINK™
Type	Taps
UPC	781810208700
UPC 12 Digit	7818102087000

Dimensions

Dimension - I Beam Thickness inch	1.000" -1.060"
Dimension - L Length Overall mm	76 mm
Dimension - Length Overall inch	3.00 in

Conductor Related

Conductor - Copper Str Size	2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Str Size Range	2 AWG-4/0 AWG
Conductor Type	CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none">UL467IEEE 837
Standards - Industry Standards Met	<ul style="list-style-type: none">UL467IEEE 837
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	6
Minimum Pack Quantity	1
Pallet Quantity	1392

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - SD208416-04_B](#)
[Specifications - YGIBW2810002N](#)