




YGIBW287502N Structural Steel Compression Grounding Connector

By Burndy
Catalog # YGIBW287502N

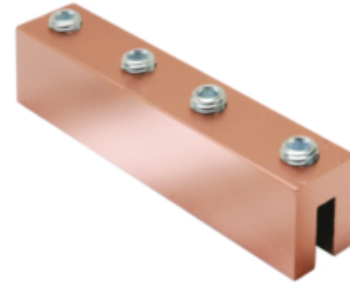

Wrought Cu Straight I-Beam Connector, 4/0 AWG, For Cu Cable.

General

Connector Type	Tap
Material	Copper
Physical Attribute - Number of Tapped Holes	2
Plated	N
Plating Type	Unplated
Trade Name	GROUNDLINK™
Type	Taps
UPC	781810232613
UPC 12 Digit	7818102326133

Dimensions

Dimension - B Length fraction	3 in
Dimension - B Length inch	3.00 in
Dimension - I Beam Thickness inch	0.690" - .0750"
Dimension - L Length Overall mm	76 mm
Dimension - Length Overall inch	3.00 in

Conductor Related

Conductor - Copper Str Size	2 AWG;4/0 AWG
Conductor - Copper Str Size A	4/0 AWG
Conductor - Copper Str Size Range	4/0 AWG
Conductor Type	CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none">UL467IEEE 837
Standards - Industry Standards Met	<ul style="list-style-type: none">UL467IEEE 837
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	6
Minimum Pack Quantity	1
Pallet Quantity	1392

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD208416-04_B](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YGIBW287502N-SPEC-EN | REV 5/2024