




# YH292C, Cu Compression H Tap, 250 kcmil-2 AWG Run, 2-14 AWG Tap

By Burndy  
Catalog # YH292C

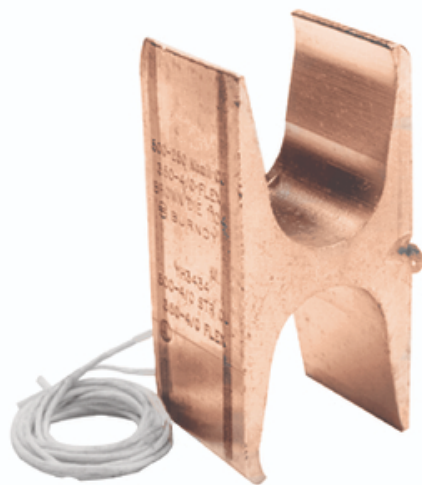

Copper Compression H Tap, Tin Plated, Accommodating the following wire sizes - Run (Main): 250 kcmil-2 AWG Class B,C, 4/0 AWG-2 AWG Class I, DLO; Tap 1: 2 AWG-6 AWG Class B, C, Solid, and 2 AWG-8 AWG Class I, DLO. See sale drawing for metric wire size accommodates

### Application

Wire Tap

### General

Catalog Number	YH292C
Color Code	Purple
Connector Type	H-TAP
Die Index	654
EU RoHS Indicator	Yes
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	CRIMPIT
Temperature Rating	194
Trade Name	CRIMPIT™
Type	Compression Taps
UPC	781810013878
UPC 12 Digit	7818100138788

### Dimensions

Dimension - Height inch	1.52 in
Dimension - L Length Overall mm	23 mm
Dimension - Length Overall inch	0.90 in
Dimension - Strip Length inch	1-1/16
Dimension - Width fraction	.90 in
Dimension - Width inch	1.52 in

### Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

### Conductor Related

Conductor - Copper Flex G Run	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Flex G Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex H Run	8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Flex H Run Range	8 AWG-4/0 AWG
Conductor - Copper Flex I Run	4/0 AWG-2 AWG
Conductor - Copper Flex I Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex I Tap	8;7;6;5;4;3;2
Conductor - Copper Flex I Tap Range	2 AWG-8 AWG
Conductor - Copper Flex K Run	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Flex K Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex K Tap	8;7;6;5;4;3;2
Conductor - Copper Flex M Run	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Flex M Run Range	2 AWG-4/0 AWG
Conductor - Copper Flex M Tap	8;7;6;5;4;3;2
Conductor - Copper Solid Tap	6;5;4;3;2
Conductor - Copper Str Run	2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Run Range	250 KCMIL-2 AWG
Conductor - Copper Str Tap	2 AWG-6 AWG
Conductor - Copper Str Tap Range	2 AWG-6 AWG
Conductor - Material	COPPER
Conductor Type	CODE/FLEX

## Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	60
Minimum Pack Quantity	1
Pallet Quantity	8640

## Product Assets

[3D Models - YH292C\\_MODEL-STEP](#)  
[3D Models - YH292C\\_MODEL-PDF](#)  
[3D Models - YH292C\\_MODEL-IGES](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_YH\\_LINEART](#)  
[Sales Drawings - SD..206566-01](#)  
[Specifications - YH292C](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YH292C-SPEC-EN | REV 8/2024