


# Compression H-Tap

By Burndy  
Catalog # YH3434

Copper Compression H Tap, Tin Plated, Accommodating the following wire sizes - Run (Main): 500 KCMIL-250 KCMIL Class B,C, 373 KCMIL-4/0 AWG DLO, 350 KCMIL-4/0 AWG Class I, 4/0 AWG Class K. See sale drawing for metric wire size accommodates

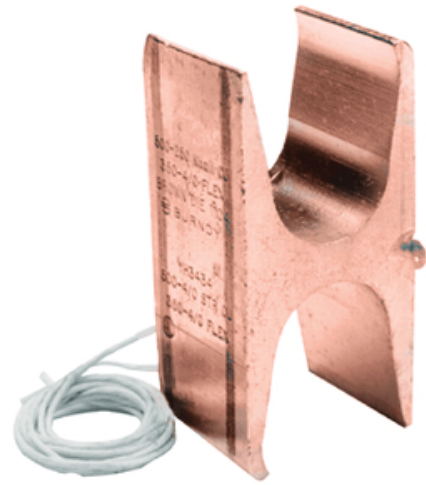

## Application

Wire Tap

## General

Catalog Number	YH3434
Color Code	Brown
Connector Type	H-TAP
Die Index	1104
EU RoHS Indicator	Yes
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	CRIMPIT
Temperature Rating	194
Trade Name	CRIMPIT™
Type	Compression Taps
UPC	781810144213
UPC 12 Digit	7818101442133

## Dimensions

Dimension - Height inch	2.43 in
Dimension - L Length Overall mm	25 mm
Dimension - Length Overall inch	1.00 in
Dimension - Strip Length inch	1-1/8
Dimension - Width fraction	1.15 in
Dimension - Width inch	2.43 in

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper Flex G Run	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex G Run Range	4/0 AWG-350 kcmil
Conductor - Copper Flex G Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex G Tap Range	4/0 AWG-350 kcmil
Conductor - Copper Flex H Run	350 kcmil
Conductor - Copper Flex H Run Range	350 kcmil
Conductor - Copper Flex H Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex H Tap Range	4/0 AWG-350 kcmil
Conductor - Copper Flex I Run	350 KCMIL-4/0 AWG
Conductor - Copper Flex I Run Range	4/0 AWG-350 kcmil
Conductor - Copper Flex I Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex I Tap Range	350 KCMIL-4/0 AWG
Conductor - Copper Flex K Run	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex K Run Range	4/0 AWG-350 kcmil
Conductor - Copper Flex K Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex K Tap Range	4/0 AWG-350 kcmil
Conductor - Copper Flex M Run	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex M Run Range	4/0 AWG-350 kcmil
Conductor - Copper Flex M Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex M Tap Range	4/0 AWG-350 kcmil
Conductor - Copper Str Run	250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Run Range	500 KCMIL-250 KCMIL
Conductor - Copper Str Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Tap Range	500 KCMIL - 4/0 AWG

Conductor - Copper Str Tap Range 500 KCMIL-4/0 AWG  
Conductor - Material COPPER  
Conductor Type CODE/FLEX

### Certifications And Compliance

Certification - CSA Approved Yes  
Certification - ETL No  
Certification - UL Recognized No  
Certification - cULus No  
Industry Standard(s) UL 486A-486B  
Standards - Industry Standards Met UL467  
Standards - RoHS Compliance Status CM  
UL Listed Yes

### Logistics

Minimum Pack Quantity 1

### Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section C - Compression Connections](#)  
[Customer Notices - Prop 65 Notice](#)  
[Product Cross Section Image\(s\) - BUR\\_YH\\_LINEART](#)  
[Sales Drawings - SD..206566-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-YH3434-SPEC-EN | REV 6/2024