


Compression H-Tap

By Burndy
Catalog # YH3939

Copper Compression H Tap, Tin Plated, Accommodating the following wire sizes - Run (Main): 750 KCMIL-500 KCMIL Class B,C, 535 KCMIL-444 KCMIL DLO, 550-450 KCMIL Class I, Tap 1: 750 KCMIL-350 KCMIL Class B,C, 535 KCMIL-313 KCMIL DLO, 550-KCMIL-350 KCMIL Class I. See sale drawing for metric wire size accommodates

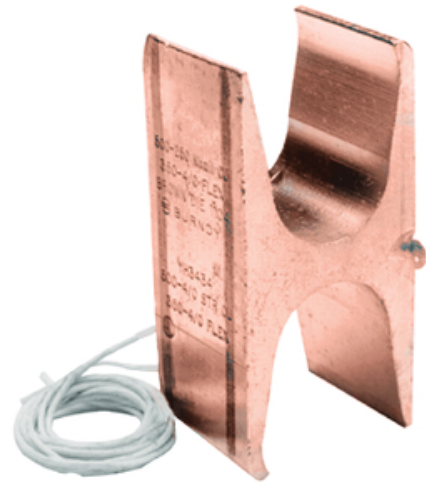

Application

Wire Tap

General

Color Code	Yellow
Connector Type	H-TAP
Die Index	KR
EU RoHS Indicator	Yes
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	CRIMPIT
Temperature Rating	194
Trade Name	CRIMPIT™
Type	Compression Taps
UPC	781810013847
UPC 12 Digit	7818100138477

Dimensions

Dimension - Height inch	2.97 in
Dimension - L Length Overall mm	32 mm
Dimension - Length Overall inch	1.25 in
Dimension - Strip Length inch	1-3/8
Dimension - Width fraction	1.50 in
Dimension - Width inch	2.97 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Flex G Run	450;500
Conductor - Copper Flex G Run Range	450-500
Conductor - Copper Flex G Tap	350;400;450;500
Conductor - Copper Flex G Tap Range	350-500
Conductor - Copper Flex H Run	500 kcmil
Conductor - Copper Flex H Run Range	500 kcmil
Conductor - Copper Flex H Tap	350;400;450;500
Conductor - Copper Flex H Tap Range	350-500
Conductor - Copper Flex I Run	550 KCMIL-450 KCMIL
Conductor - Copper Flex I Tap	350;400;450;500
Conductor - Copper Flex I Tap Range	550 KCMIL-350 KCMIL
Conductor - Copper Flex K Run	450;500
Conductor - Copper Flex K Tap	350;400;450;500
Conductor - Copper Flex M Run	450;500
Conductor - Copper Flex M Tap	350;400;450;500
Conductor - Copper Str Run	500;550;600;700;750
Conductor - Copper Str Run Range	750 KCMIL-500 KCMIL
Conductor - Copper Str Tap	350;400;450;500;550;600;700
Conductor - Copper Str Tap Range	750 KCMIL-350 KCMIL
Conductor - Material	COPPER
Conductor Type	CODE/FLEX

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	CM

Status
UL Listed Yes

Logistics

Carton Quantity 30
Minimum Pack Quantity 1
Pallet Quantity 2880

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YH_LINEART](#)
[Sales Drawings - SD..206566-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YH3939-SPEC-EN | REV 5/2024