


YH4444, Compression H-Tap

By Burndy
Catalog # [YH4444](#)

Copper Compression H Tap, Tin Plated, Accommodating the following wire sizes - Run (Main): 1000 KCMIL-750 KCMIL Class B,C, 777 KCMIL-535 KCMIL DLO, 750-500 KCMIL Class I, Tap 1: 777 KCMIL-535 KCMIL DLO, 750 KCMIL-350 KCMIL Class I. See sale drawing for metric wire size accommodates

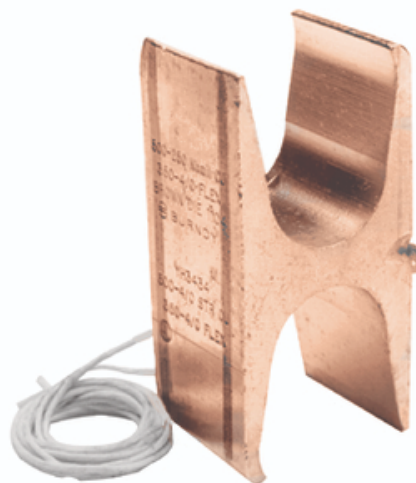

Application

Wire Tap

General

Catalog Number	YH4444
Color Code	White
Connector Type	H-TAP
Die Index	1102
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Temperature Rating	194
Trade Name	CRIMPIT™
Type	Compression Taps
UPC	781810013854
UPC 12 Digit	7818100138544

Dimensions

Dimension - Height inch	3.38 in
Dimension - L Length Overall mm	610 mm
Dimension - Length Overall inch	1 in
Dimension - Strip Length inch	1-1/8
Dimension - Width fraction	1.70 in
Dimension - Width inch	3.38 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Flex G Run	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex G Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex G Tap	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex G Tap Range	500 kcmil-700 kcmil
Conductor - Copper Flex H Run	700 kcmil
Conductor - Copper Flex H Run Range	700 kcmil
Conductor - Copper Flex H Tap	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex H Tap Range	500 kcmil-700 kcmil
Conductor - Copper Flex I Run	750 KCMIL-500 KCMIL
Conductor - Copper Flex I Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex I Tap	500 kcmil;550 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex I Tap Range	750 KCMIL-350 KCMIL
Conductor - Copper Flex K Run	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex K Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex K Tap	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex K Tap Range	500 kcmil-700 kcmil
Conductor - Copper Flex M Run	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex M Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex M Tap	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex M Tap Range	500 kcmil-700 kcmil
Conductor - Copper Str Run	700 kcmil;750 kcmil;800 kcmil;850 kcmil;900 kcmil;1000 kcmil
Conductor - Copper Str Run Range	1000 KCMIL-750 KCMIL
Conductor - Copper Str Tap	750 kcmil;800 kcmil;850 kcmil;900 kcmil;1000 kcmil
Conductor - Copper Str Tap Range	1000 KCMIL-750 KCMIL
Conductor - Material	COPPER
Conductor Type	CODE/FLEX

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	2250

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YH_LINEART](#)
- [Sales Drawings - SD..206566-01](#)
- [Specifications - YH4444](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-YH4444-SPEC-EN | REV 8/2024