




YH6C6C, Copper Compression H-Tap, Run: #6-10 AWG, Tap: #6-14 AWG, Tin Plated

By Burndy
Catalog # YH6C6C

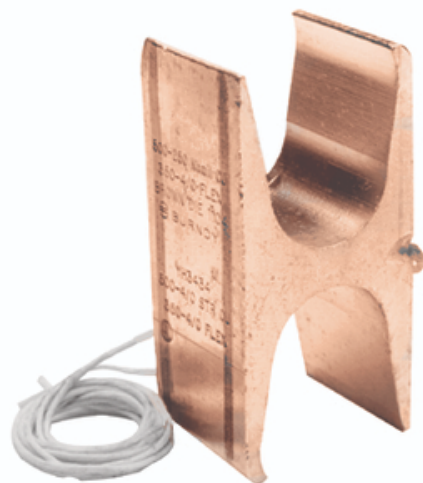

Copper Compression H Tap, Tin Plated, Accommodating the following wire sizes - Run (Main): 6 AWG-10 AWG Class B,C, 6 AWG-10 AWG Class I, DLO, Tap 1: 6 AWG-14 AWG Class B,C, 6 AWG-14 AWG Class I, DLO. See sale drawing for metric wire size accommodates

Application

Wire Tap

General

Catalog Number	YH6C6C
Color Code	Orange
Connector Type	H-TAP
Die Index	BG
EU RoHS Indicator	Yes
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	CRIMPIT
Temperature Rating	194
Trade Name	CRIMPIT™
Type	Compression Taps
UPC	781810042373
UPC 12 Digit	7818100423733

Dimensions

Dimension - Height inch	0.81 in
Dimension - L Length Overall mm	15 mm
Dimension - Length Overall inch	0.60 in
Dimension - Strip Length inch	3/4
Dimension - Width fraction	.39 in
Dimension - Width inch	0.81 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Flex G Run	8;7;6
Conductor - Copper Flex G Run	8-6
Range	
Conductor - Copper Flex G Tap	14;8;7;6
Conductor - Copper Flex G Tap	14-6
Range	
Conductor - Copper Flex H Run	6 AWG
Conductor - Copper Flex H Run	6 AWG
Range	
Conductor - Copper Flex H Tap	14;8;7;6
Conductor - Copper Flex H Tap	14-6
Range	
Conductor - Copper Flex I Run	6 AWG-10 AWG
Conductor - Copper Flex I Tap	14;8;7;6
Conductor - Copper Flex I Tap	6 AWG-14 AWG
Range	
Conductor - Copper Flex K Run	8;7;6
Conductor - Copper Flex K Tap	14;8;7;6
Conductor - Copper Flex M Run	8;7;6
Conductor - Copper Flex M Tap	14;8;7;6
Conductor - Copper Str Run	10;9;8;7;6
Conductor - Copper Str Run	6 AWG-10 AWG
Range	
Conductor - Copper Str Tap	14;12;10;9;8;7;6
Conductor - Copper Str Tap	6 AWG-14 AWG
Range	
Conductor - Material	COPPER
Conductor Type	CODE/FLEX

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	150
Minimum Pack Quantity	1
Pallet Quantity	13500

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_YH_LINEART](#)
[Sales Drawings - SD..206566-01](#)
[Specifications - YH6C6C](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-YH6C6C-SPEC-EN | REV 8/2024