




YNTA36R, Aluminum T-Tap Connector

By Burndy
Catalog # [YNTA36R](#)

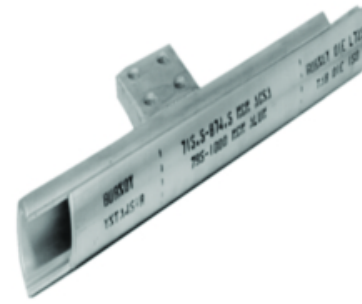

Terminal Tee Taps,WIRE: 477 kcmil ACSR 500-556.5 kcmil
ALUM. INDEX: 720, 1.75" Spacing.

General

Connector Type	Tap
Die Index	720
Material	Aluminum
UPC	781810053652
UPC 12 Digit	7818100536522

Dimensions

Dimension - B Length inch	4.19 in
Dimension - Bolt Size fraction	1/2 in
Dimension - Bolt Size inch	0.5 in
Dimension - D inch	3.12 in
Dimension - Height fraction	5-4/25 in
Dimension - Height inch	5.16 in
Dimension - Length Overall inch	16.29 in
Dimension - Outside Diameter inch	1.41 in
Dimension - Pad Width inch	2.25 in

Conductor Related

Conductor - ACAR Str Size	477 KCMIL
Conductor - ACAR Str Size Range	500 KCMIL - 556.5 KCMIL
Conductor - ACSR Str Size	477.0 (24/7) Kcmil;477.0 (26/7) Kcmil
Conductor - ACSR Str Size Range	477.0 (24/7) Kcmil-477.0 (26/7) Kcmil
Conductor - AL Str Size	500;550;556.5
Conductor - AL Str Size Range	500-556.5

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sd065201](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YNTA36R-SPEC-EN | REV 8/2023