

YP28C28, Figure 6-shaped Copper Tap Connector

By Burndy
Catalog # [YP28C28](#)

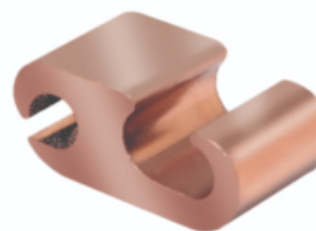


Figure 6 - shaped, wide range-taking CU compression tap connector for primary service taps and secondary service drops, Width: 1.00.

Application

For Extra Wide Range Of Copper And Primary Service Taps And Secondary Service Drops

General

Catalog Number	YP28C28
Connector Type	Tap
Die Index	D
EU RoHS Indicator	Yes
Material	Copper
Plated	Y
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YP-C
UPC	781810117958
UPC 12 Digit	7818101179588

Dimensions

Dimension - D inch	1.00 in
Dimension - Height inch	2.06 in
Dimension - L Length Overall mm	25 mm

Conductor Related

Conductor - Copper Str Run	2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Str Run Range	2/0 AWG-4/0 AWG
Conductor - Copper Str Tap	2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Str Tap Range	2/0 AWG-4/0 AWG

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	7400

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YP-C_LineArt](#)
- [Sales Drawings - SC058072-01](#)
- [Specifications - YP28C28](#)