

YP2C2, Figure 6-shaped Copper Tap Connector

By Burndy
Catalog # [YP2C2](#)

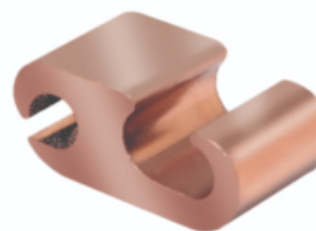


Figure 6 - shaped, wide range-taking CU compression tap connector for primary service taps and secondary service drops, Width: .75 IN.

Application

For Extra Wide Range Of Copper And Primary Service Taps And Secondary Service Drops

General

Catalog Number	YP2C2
Connector Type	Tap
Die Index	O
EU RoHS Indicator	Yes
Material	Copper
Plated	Y
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YP-C
UPC	781810117903
UPC 12 Digit	7818101179033

Dimensions

Dimension - Height inch	1.45 in
Dimension - L Length Overall mm	19 mm
Dimension - Length Overall inch	0.75 in

Conductor Related

Conductor - Copper Solid Run	6 AWG
Conductor - Copper Solid Tap	6 AWG
Conductor - Copper Str Run	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Run Range	6 AWG-2 AWG
Conductor - Copper Str Tap	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Tap Range	6 AWG-2 AWG

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	11600

Product Assets

- [3D Models - YP2C2_MODEL-IGES](#)
- [3D Models - YP2C2_MODEL-PDF](#)
- [3D Models - YP2C2_MODEL-STEP](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YP-C_LineArt](#)
- [Sales Drawings - SC058072-01](#)
- [Specifications - YP2C2](#)



A Hubbell brand