


Compression Splice

By Burndy
Catalog # YR2C2WT

2 AWG CU, Long Barrel, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, BROWN Color Code, 10 Die Index.

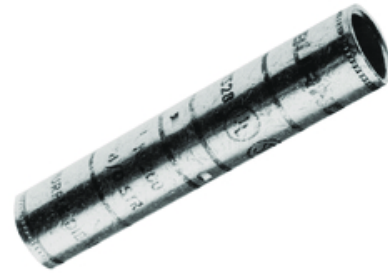

Application

Wire Splice

General

Color Code	Brown
Connector Type	STANDARD BARREL
Die Index	10
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Temperature Rating	194
UPC	781810064771
UPC 12 Digit	7818100647711

Dimensions

Dimension - B Length fraction	1-1/4 in
Dimension - B Length inch	1.25 in
Dimension - L Length Overall mm	77 mm
Dimension - Length Overall inch	3.03 in
Dimension - Outside Diameter inch	0.42 in
Dimension - Strip Length inch	1-3/8

Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

Conductor Related

Conductor - Copper Solid Size	2 AWG
Conductor - Copper Solid Size Range	2 AWG
Conductor - Copper Str Size	2 AWG
Conductor - Copper Str Size Range	2 AWG
Conductor - Material	COPPER
Conductor Size	2 AWG-2 AWG
Conductor Type	CODE
Wire Size	#2 AWG

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	25
Minimum Pack Quantity	25

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 210321](#)