




YRA25U, Aluminum Lug, Prefilled with Oxide Inhibitor

By Burndy
Catalog # [YRA25U](#)

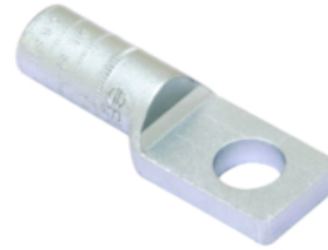

AL compression lug for joining AL and CU cable to transformer and equipment pads, Prefilled with PENETROX, Barrel Length: 1.43 IN.

General

Die Index	249;K-840
Material	Aluminum
Physical Attribute - Pad Configuration	1 Hole
Physical Attribute - Tongue Type	Standard
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Trade Name	HYLUG™
UPC	781810810149
UPC 12 Digit	7818108101499

Dimensions

Dimension - B Length fraction	3-1/4 in
Dimension - B Length inch	1.43 in
Dimension - D inch	1.28 in
Dimension - L Length Overall mm	81 mm
Dimension - Length Overall inch	3.19 in
Dimension - N inch	0.62 in
Dimension - Outside Diameter inch	0.91 in
Dimension - Strip Length inch	1.50 in
Physical Attribute - Tongue Angle	Straight
Thickness - Pad	0.25 in

Conductor Related

Conductor - ACSR Str Size	1/0 (6/1) Raven AWG
Conductor - AL Str Size	1/0 AWG
Conductor - Copper Str Size	1/0 AWG

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	14800

Product Assets

[3D Models - YRA25U_MODEL-STEP](#)
[3D Models - YRA25U_MODEL-PDF](#)
[3D Models - YRA25U_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sd077273-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YRA25U-SPEC-EN | REV 8/2023