




YS25UCG1, Splice Kit - Insulated

By Burndy
Catalog # [YS25UCG1](#)

URD Insulator Splice Kit, 1/0 AWG Comp, 1/0 Str Al, 1/0 AWG (6-1) ACSR, 1/0 Str Cu, 600 V.

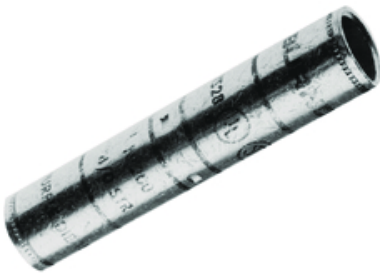

General

Connector Type	Splice
Die Index	243;BG
Insulation	Y
Insulation Type	Diaform
Material	Aluminum
Plated	N
Plating Type	Unplated
UPC	781810187753
UPC 12 Digit	7818101877533

Dimensions

Dimension - B Length inch	0.87 in
Dimension - Length Overall inch	2 in

Conductor Related

Conductor - ACSR Str Size A	1/0 (6/1) Raven AWG
Conductor - ACSR Str Size A Range	1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B	1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B Range	1/0 (6/1) Raven AWG
Conductor - AL Str Size A	1/0 AWG
Conductor - AL Str Size A Range	1/0 AWG
Conductor - AL Str Size B	1/0 AWG
Conductor - AL Str Size B Range	1/0 AWG
Conductor - Copper Str Size A	1/0
Conductor - Copper Str Size A Range	1/0

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	1440

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Product Cross Section Image\(s\) - BUR_YSCG_URD_INSUL_SPLICE_LineArt](#)
[Sales Drawings - 6667](#)



A proud member of the Hubbell Family.