




YS26, Cu Compression Splice, Long Barrel, 2/0 AWG

By Burndy
Catalog # YS26

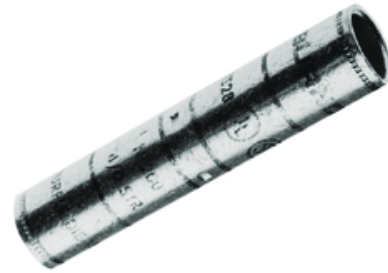

2/0 AWG CU, Long Barrel, Internal Chamfer, Tin Plated,
UL/CSA, 90°C, Up to 35kV, BLACK Color Code, 13 Die Index

Application

Wire Splice

General

Color Code	Black
Connector Type	LONG BARREL
Die Index	13
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YS, Long Barrel
UPC	781810507605
UPC 12 Digit	7818105076055

Dimensions

Dimension - B Length inch	1.45 in
Dimension - L Length Overall mm	84 mm
Dimension - Length Overall inch	3.30 in
Dimension - Strip Length inch	1-1/2

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Str Navy Size	125 (61) Navy
Conductor - Copper Str Size	700 KCMIL;750 KCMIL
Conductor - Copper Str Size Range	2/0 AWG
Conductor - Material	COPPER
Conductor Size	2/0 AWG
Conductor Type	CODE
Wire Size	700 KCMIL; 750 KCMIL

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	10
Minimum Pack Quantity	1

Product Assets

[3D Models - YS26_MODEL-STEP](#)
[3D Models - YS26_MODEL-IGES](#)
[3D Models - YS26_MODEL-PDF](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD007774-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YS26-SPEC-EN | REV 5/2024

