


YS26UCG1, Splice Kit - Insulated

By Burndy
Catalog # [YS26UCG1](#)

URD Insulator Splice Kit, 2/0 AWG Comp, 2/0 Str Al, 2/0 AWG (6-1) ACSR, 2/0 Str Cu, 600 V.

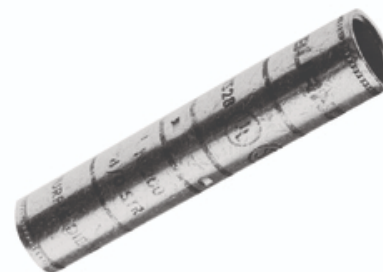

General

Catalog Number	YS26UCG1
Connector Type	Splice
Die Index	249;840
Insulation	Y
Insulation Type	Diaform
Material	Aluminum
Plated	N
Plating Type	Unplated
UPC	781810187807
UPC 12 Digit	7818101878077

Dimensions

Dimension - B Length inch	1.9 in
Dimension - Length Overall inch	4.12 in

Conductor Related

Conductor - ACSR Str Size A	2/0 (6/1) Quail AWG
Conductor - ACSR Str Size A Range	2/0 (6/1) Quail AWG
Conductor - ACSR Str Size B	2/0 (6/1) Quail AWG
Conductor - ACSR Str Size B Range	2/0 (6/1) Quail AWG
Conductor - AL Str Size A	2/0 AWG
Conductor - AL Str Size A Range	2/0 AWG
Conductor - AL Str Size B	2/0 AWG
Conductor - AL Str Size B Range	2/0 AWG
Conductor - Copper Str Size A	2/0 AWG
Conductor - Copper Str Size A Range	2/0 AWG
Conductor - Copper Str Size B	2/0 AWG
Conductor - Copper Str Size B Range	2/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	900

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section K - Underground Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_YSCG_URD_INSUL_SPLICE_LineArt](#)
[Sales Drawings - 6667](#)
[Specifications - YS26UCG1](#)



A Hubbell brand