


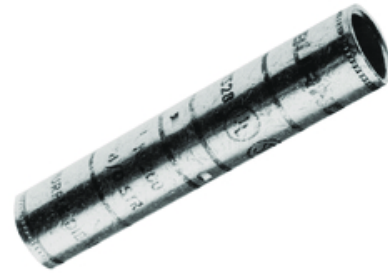

YS27UCG1, URD Insulator Splice Kit

By Burndy
Catalog # YS27UCG1

URD Insulator Splice Kit, 3/0 AWG Comp, 3/0 Str Al, 3/0 AWG (6-1) ACSR, 3/0 Str Cu, 600 V.



General

Connector Type	Splice
Die Index	249;840
Insulation	Y
Insulation Type	Diaform
Material	Aluminum
Plated	N
Plating Type	Unplated
UPC	781810187852
UPC 12 Digit	7818101878522

Dimensions

Dimension - B Length inch	1.9 in
Dimension - Length Overall inch	4.12 in

Conductor Related

Conductor - ACSR Str Size A	3/0 (6/1) Pigeon AWG
Conductor - ACSR Str Size A Range	3/0 (6/1) Pigeon AWG
Conductor - ACSR Str Size B	3/0 (6/1) Pigeon AWG
Conductor - ACSR Str Size B Range	3/0 (6/1) Pigeon AWG
Conductor - AL Str Size A	3/0 AWG
Conductor - AL Str Size A Range	3/0 AWG
Conductor - AL Str Size B	3/0 AWG
Conductor - AL Str Size B Range	3/0 AWG
Conductor - Copper Str Size A	3/0 AWG
Conductor - Copper Str Size A Range	3/0 AWG
Conductor - Copper Str Size B	3/0 AWG
Conductor - Copper Str Size B Range	3/0 AWG

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	1440

Product Assets

[Sales Drawings - 6667](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YS27UCG1-SPEC-EN | REV 8/2023