




YS29PULL, Compression Splice, 250 kcmil Cu, Long Barrel

By Burndy
Catalog # [YS29PULL](#)

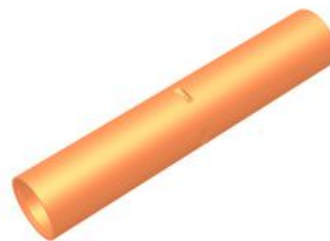

250 kcmil CU, Long Barrel, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, YELLOW Color Code, 16 Die Index.

Application

Wire Splice

General

Catalog Number	YS29PULL
Color Code	Yellow
Connector Type	LONG BARREL
Die Index	16
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Bright
Sub Brand	SPLICE, HYLINK
Trade Name	HYLINK™
Type	YS
UPC	781810090176
UPC 12 Digit	7818100901766

Dimensions

Dimension - B Length inch	1.58 in
Dimension - L Length Overall mm	91 mm
Dimension - Length Overall inch	3.58 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Str Size	250 kcmil
Conductor - Copper Str Size Range	250 kcmil
Conductor - Material	COPPER
Conductor Size	250 KCMIL
Conductor Type	CODE

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	10
Minimum Pack Quantity	1

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 30018849](#)
[Specifications - YS29PULL](#)