


# Compression Splice

By Burndy  
Catalog # YS37

Copper Compression Splice, 650 Kcmil, 6.10" Splice Length, Long Barrel, Tin Plated.

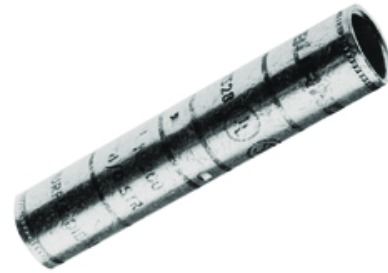

## Application

Wire Splice

## General

Color Code	Orange
Connector Type	LONG BARREL
Die Index	23
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYLINK™
UPC	781810080863
UPC 12 Digit	7818100808633

## Dimensions

Dimension - B Length inch	2.75 in
Dimension - L Length Overall mm	155 mm
Dimension - Length Overall inch	6.10 in
Dimension - Strip Length inch	2-13/16

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper Str Navy Size	650 (127)
Conductor - Copper Str Size	650
Conductor - Copper Str Size Range	650 kcmil
Conductor - Material	COPPER
Conductor Size	650 KCMIL
Conductor Type	CODE

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	6
Minimum Pack Quantity	6

## Product Assets

[Sales Drawings - SD007774-01](#)