




# YS39, Cu Compression Splice, 750 kcmil

By Burndy  
Catalog # YS39

750 kcmil, CU, Long Barrel SPLICE

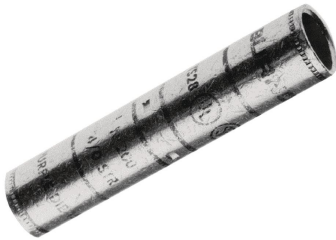

## Features

- Copper seamless barrel with center stop indentations to indicate when wire is fully inserted into each side of the barrel
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors clearly marked with color coding

## Application

Wire Splice

## Specifications

|                                    |                                                      |
|------------------------------------|------------------------------------------------------|
| Certification - UL Recognized      | No                                                   |
| Buy American Compliant             | No                                                   |
| Certification - cULus              | No                                                   |
| EU RoHS Indicator                  | Yes                                                  |
| Buy America(n) Qualified           | BABA Compliant (All status valid till December 2026) |
| Industry Standard(s)               | UL 486A-486B                                         |
| Certification - ETL                | No                                                   |
| Standards - Industry Standards Met | UL 486A-486B                                         |
| Standards - RoHS Compliance Status | CM                                                   |
| UL Listed                          | Yes                                                  |
| Certification - CSA Approved       | Yes                                                  |

## Conductor

|                                   |           |
|-----------------------------------|-----------|
| Conductor - Material              | COPPER    |
| Wire Size                         | 750 kcmil |
| Conductor - Copper Str Size       | 750 kcmil |
| Conductor Size                    | 750 KCMIL |
| Conductor Type                    | CODE      |
| Conductor - Copper Str Size Range | 750 kcmil |

## Configuration

|                |             |
|----------------|-------------|
| Connector Type | LONG BARREL |
|----------------|-------------|

## Current

|                   |       |
|-------------------|-------|
| Voltage Rating    | 35 kV |
| Voltage - Maximum | 35000 |

## Dimensions

|                                 |           |
|---------------------------------|-----------|
| Package Height                  | 0.000 in  |
| Package Weight                  | 0.000 lb. |
| Package Length                  | 0.000 in  |
| Package Width                   | 0.000 in  |
| Dimension - L Length Overall mm | 162 mm    |
| Dimension - Strip Length inch   | 2-7/8     |
| Dimension - B Length inch       | 2.81 in   |
| Dimension - Length Overall inch | 6.38 in   |

## General

|                        |                      |
|------------------------|----------------------|
| Trade Name             | HYLINK™              |
| Die Index              | 24                   |
| Feature - Barrel Type  | Long                 |
| Feature - Barrel Style | Chamfered            |
| Plated                 | Y                    |
| Color Code             | Black                |
| Sub Brand              | HYLINK               |
| UPC                    | 781810526859         |
| Type                   | YS, Long Barrel      |
| Material               | Copper               |
| Plating Type           | Tin - Electro Plated |
| Finish Type            | Tin-Plated           |
| UPC 12 Digit           | 781810526859         |
| UPC 14 Digit GTIN      | 00781810526859       |

## Logistics

|                       |   |
|-----------------------|---|
| Minimum Pack Quantity | 1 |
| Carton Quantity       | 6 |

## Product Assets

[Catalog \[English\]](#)