




Compression Splice

By Burndy
Catalog # YS44A1

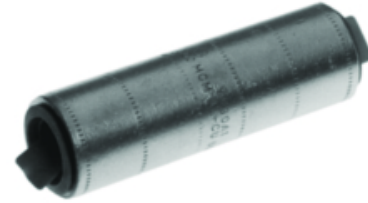

AL Splice, AL9CU, Internal Chamfer, Tin Plated, Prefilled PENETROX™ A13 oxide inhibitor, End Cap, UL/CSA, 90°C, Up to 35kV, Color Code, Die Index.

Application

Wire Splice

General

Color Code	Brown
Connector Type	DUAL RATED
Die Index	302
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	ALUMINUM
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Temperature Rating	194
Trade Name	HYLINK™
Type	YS-A, Standard Barrel
UPC	781810766255
UPC 12 Digit	7818107662555

Dimensions

Dimension - B Length fraction	2-13/16 in
Dimension - B Length inch	2.84 in
Dimension - L Length Overall mm	151 mm
Dimension - Length Overall inch	5.94 in
Dimension - Outside Diameter inch	1.84 in
Dimension - Strip Length inch Length	3-1/8 in 5.94 in
Outside Diameter	1.84 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - AL Str Size	1000 KCMIL
Conductor - AL Str Size Range	1000 kcmil
Conductor - Copper Str Compact Size	1000
Conductor - Copper Str Size	1000 KCMIL
Conductor - Copper Str Size Range	1000 kcmil
Conductor - Material	ALUMINUM / COPPER
Conductor Size	1000 KCMIL
Conductor Type	CODE
Wire Size	1000 KCMIL

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	15
Minimum Pack Quantity	1
Pallet Quantity	1350

Product Assets

- [3D Models - YS44A1_MODEL-PDF](#)
- [3D Models - YS44A1_MODEL-IGES](#)
- [3D Models - YS44A1_MODEL-STEP](#)
- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Sales Drawings - SD..073942-01](#)



A proud member of the Hubbell Family.

