




YSCM104, Seamless Parallel Compression Splice Connector, 82,870-103,630 Circular Mils Cu

By Burndy
Catalog # [YSCM104](#)

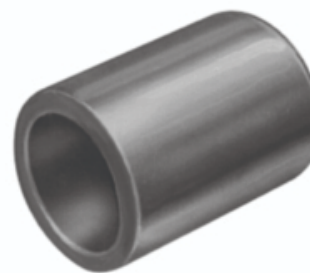

82,870 - 103,630 Circular Mils, CU, Internal Chamfer, Tin Plated, UL/CSA 90° Up to 35kV, Pink Color Code, 12 Die Index.

Application

Wire Splice

General

Catalog Number	YSCM104
Color Code	Pink
Connector Type	Splice
Die Index	12
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YSCM
UPC	781810358542
UPC 12 Digit	7818103585422

Dimensions

Dimension - L Length Overall mm	18 mm
Dimension - Length Overall inch	0.69 in
Dimension - Outside Diameter inch	0.57 in
Dimension - Strip Length inch	15/16

Electrical Ratings

Voltage - Maximum	600 V
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Str Size	1 AWG
Conductor - Copper Str Size Range	8 AWG
Conductor - Material	COPPER
Conductor Size	82,870-103630 CMILS
Conductor Type	CODE
Wire Range	82,870 - 103,630 Circular Mils

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	Yes
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	200
Minimum Pack Quantity	1
Pallet Quantity	92800

Product Assets

[3D Models - YSCM104_MODEL-STEP](#)
[3D Models - YSCM104_MODEL-IGES](#)
[3D Models - YSCM104_MODEL-PDF](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50094201](#)
[Specifications - YSCM104](#)



A Hubbell brand