


# Nylon Splice For 12 - 10 AWG

By Burndy  
Catalog # YSE10

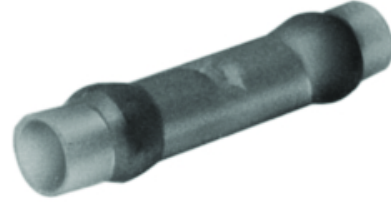

Copper Butt Splice, w/ Inspection Window, AN 12-10, 1.15" Splice Length, Nylon Insulated, Funnel Entry, Tin Plated, 600 Volts Max.

## General

Color	Yellow
Color Code	Yellow
Connector Type	Seamless Butt Splice
Construction Material - Main	TIN PLATED COPPER
EU RoHS Indicator	Yes
Insulation	Y
Insulation Type	Nylon
Material	Copper
Plated	Y
Plating Type	Tin
Temperature Rating	105
Trade Name	INSULINK™
UPC	781810803844
UPC 12 Digit	7818108038444

## Dimensions

Dimension - B Length fraction	3/10 in
Dimension - B Length inch	0.30 in
Dimension - Diameter Max Size inch	0.22 in
Dimension - Length Overall inch	1.15 in
Dimension - Outside Diameter inch	0.21 in
Dimension - Strip Length inch	23/64

## Electrical Ratings

Voltage - Maximum	600 V
Voltage Rating	600 V

## Conductor Related

Conductor - Copper Str Aircraft Size	AN 12;AN 10
Conductor - Copper Str Aircraft Size Range	AN 12-AN 10
Conductor - Copper Str Size	12;10
Conductor - Copper Str Size Range	12-10
Conductor Size	12 - 10 AWG
Conductor Type	CU C Str-Size

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL486
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	1000
Minimum Pack Quantity	1000
Pallet Quantity	99999

## Product Assets

[3D Models - YSE10\\_MODEL-IGES](#)  
[3D Models - YSE10\\_MODEL-STEP](#)  
[3D Models - YSE10\\_MODEL-PDF](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Sales Drawings - 50094194](#)

