




YSH3434 Compression H-Tap Connector

By Burndy
Catalog # [YSH3434](#)

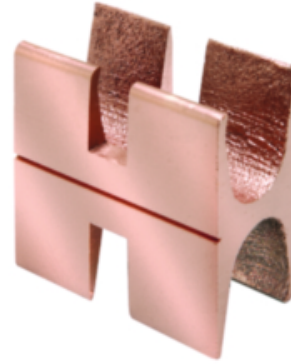

Copper Split Compression Wye Tap Connector, 500-4/0 (350-4/0), Provides maximum design and installation flexibility.

Application

For High Voltage (15 KV) Power Cables With Copper Conductors

General

Color Code	Brown
Connector Type	H-Tap
Die Index	1104
EU RoHS Indicator	Yes
Material	Copper
Plated	Y
Plating Type	Tin
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	Taps
UPC	781810036976
UPC 12 Digit	7818100369766

Dimensions

Dimension - Height inch	2.43 in
Dimension - Length Overall inch	3.00 in
Dimension - Strip Length inch	1 1/2
Dimension - Width inch	1.15 in
Dimension - Width mm	29 mm

Conductor Related

Conductor - Copper Str Run	250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Run Range	250- 500 kcmil
Conductor - Copper Str Tap	4/0 AWG;250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Tap Range	4/0 AWG-500 kcmil

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	1200

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YSH_LineArt](#)
[Sales Drawings - 20880601](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YSH3434-SPEC-EN | REV 5/2024