




YSH3931 Compression H-Tap Connector

By Burndy
Catalog # [YSH3931](#)

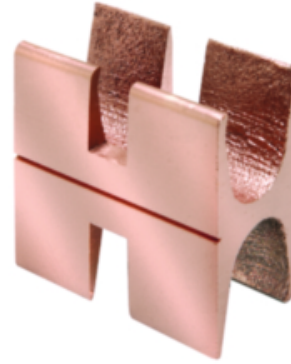

Copper Splice, 750 - 350 Kcm (Run), 4/0 - 1/0 AWG (350-1/0) (Tap 1), #1-#6 AWG (1-8) (Tap 2), #2-#14 AWG (2-14) (Tap 3), KR Index.

General

Color Code	Yellow
Connector Type	H-Tap
Die Index	KR
Material	Copper
Plated	Y
Plating Type	Tin
Type	Taps
UPC	781810038413
UPC 12 Digit	7818100384133

Dimensions

Dimension - Height inch	2.97 in
Dimension - Length Overall inch	3.00 in
Dimension - Strip Length inch	1 1/2
Dimension - Width inch	1.50 in
Dimension - Width mm	38 mm

Conductor Related

Conductor - Copper Flex G Run	350 kcmil;400 kcmil;450 kcmil;500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex G Run Range	350 kcmil-700 kcmil
Conductor - Copper Flex G Tap	1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex G Tap Range	1/0 AWG-350 kcmil
Conductor - Copper Flex H Run	350 kcmil;400 kcmil;450 kcmil;500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex H Run Range	350 kcmil-700 kcmil
Conductor - Copper Flex H Tap	1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Flex H Tap Range	1/0 AWG-350 kcmil
Conductor - Copper Str Run	350 kcmil;400 kcmil;450 kcmil;500 kcmil;550 kcmil;600 kcmil;700 kcmil;750 kcmil
Conductor - Copper Str Run Range	350 kcmil-750 kcmil
Conductor - Copper Str Tap	1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Str Tap Range	1/0 -350 kcmil

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	20
Minimum Pack Quantity	20
Pallet Quantity	960

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YSH3931-SPEC-EN | REV 8/2023