




YSHG3429 Compression H-Tap Connector

By Burndy
Catalog # [YSHG3429](#)

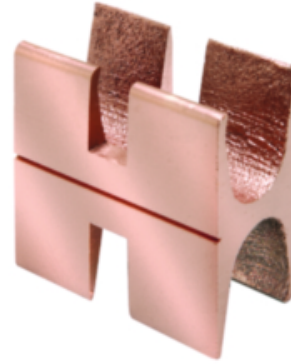

Copper Compression Double H- Tap Connector, 3/0 - 1/0 AWG (Tap 1)/ 1 - 4 AWG (Tap 2)/ 8 -14 AWG (Tap 3), # 6 Rebar/ 3/4" Ground Rod/ 400 to 4/0 kcmil Cu Cable.

Application

For Direct Burial In Earth Or Concrete

General

Connector Type	H-Tap
Die Index	1104
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	HYGROUND®
Type	Taps
UPC	781810129715
UPC 12 Digit	7818101297155

Dimensions

Dimension - Length Overall inch	2.44 in
Dimension - Width inch	2.23 in
Dimension - Width mm	57 mm

Conductor Related

Conductor - Copper Str Run	4/0 AWG;250 kcmil;300 kcmil;350 kcmil;400 kcmil
Conductor - Copper Str Run Range	4/0 AWG-400 kcmil
Conductor - Copper Str Tap	3/0 - 1/0 AWG (Tap 1)/ 1 - 4 AWG (Tap 2)/ 8 -14 AWG (Tap 3)
Conductor - Copper Str Tap Range	3/0 - 1/0 AWG (Tap 1)/ 1 - 4 AWG (Tap 2)/ 8 -14 AWG (Tap 3)
Conductor - Rebar Run	6
Conductor - Rebar Run Range	6
Conductor - Rod Run	3/4 in
Conductor - Rod Run Range	3/4 in

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 467, Direct Burial
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	2880

Product Assets

- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Product Cross Section Image\(s\) - BUR_YSHG_LineArt](#)
- [Sales Drawings - SD210382-01_A](#)



A proud member of the Hubbell Family.

