




YSHG3939 Compression H-Tap Connector

By Burndy
Catalog # [YSHG3939](#)

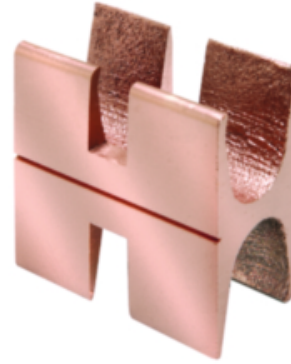

Copper Compression Double H- Tap Connector, 1" Ground Rod or 500 kcmil (Run), 500 -350 kcmil (Tap).

General

Connector Type	H-Tap
Die Index	KR
Material	Copper
Physical Attribute - Number of Crimps Required	2
Plated	N
Plating Type	Unplated
Trade Name	HYGROUND®
Type	Taps
UPC	781810129562
UPC 12 Digit	7818101295622

Conductor Related

Conductor - Copper Str Run Range	500 kcmil
Conductor - Copper Str Tap Range	500-350 kcmil
Conductor - Rod Run Range	1" Ground rod

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 467, Direct Burial
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	1440

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD210382-01_A](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YSHG3939-SPEC-EN | REV 5/2024