




YSHG4429 Compression H-Tap Connector

By Burndy
Catalog # [YSHG4429](#)

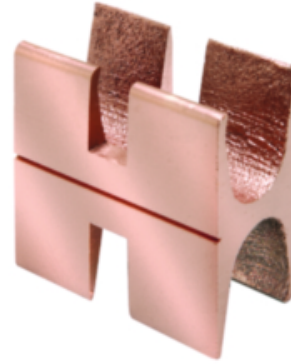

Copper Compression Double H- Tap Connector, 2 AWG - 250 kcmil (Tap), #8 & #9 Rebar/ 1" Ground Rod.

Application

For Direct Burial In Earth Or Concrete

General

Connector Type	H-Tap
Die Index	KR
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	HYGROUND®
Type	Taps
UPC	781810128657
UPC 12 Digit	7818101286577

Dimensions

Dimension - Length Overall inch	2.44 in
Dimension - Width inch	3.22 in
Dimension - Width mm	82 mm

Conductor Related

Conductor - Copper Str Tap	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Tap Range	2 AWG-250 kcmil
Conductor - Rebar Run	8 ;9
Conductor - Rebar Run Range	8 -9
Conductor - Rod Run	1 in
Conductor - Rod Run Range	1 in

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 467, Direct Burial
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	1440

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YSHG4429_LineArt](#)
[Sales Drawings - SD210382-01_A](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-YSHG4429-SPEC-EN | REV 5/2024