




YSHG4429TN Compression H-Tap Connector

By Burndy
Catalog # [YSHG4429TN](#)

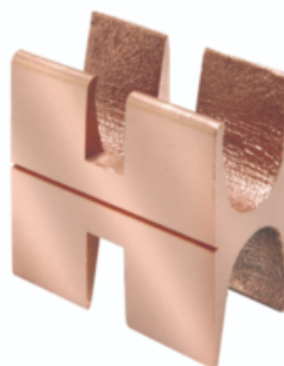

Tin plated Copper Compression Double H- Tap Connector, 2 AWG - 250 kcmil (Tap), #8 & #9 Rebar/ 1" Ground Rod.

General

Catalog Number	YSHG4429TN
Connector Type	H-Tap
Die Index	KR
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYGROUND®
Type	Taps
UPC	781810327326
UPC 12 Digit	7818103273266

Conductor Related

Conductor - Copper Str Tap	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Tap Range	2 AWG-250 kcmil

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 467, Direct Burial
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	2880

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Specifications - YSHG4429TN](#)