




Uninsulated Parallel Splice For 275,000 - 211,500 cmils

By Burndy
Catalog # [YSM292](#)

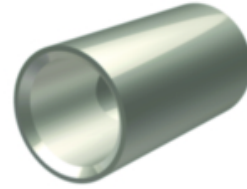

Uninsulated Parallel Splice For 275,000 - 211,500 cmils.

General

Connector Type	Parallel Splice
Feature - Barrel Style	Chamfered
Material	Copper
Plated	Y
Plating Type	Tin
Trade Name	HYLINK™
UPC	781810083680
UPC 12 Digit	7818100836800

Dimensions

Dimension - Length Overall inch	1.38 in
Dimension - Outside Diameter inch	0.75 in
Dimension - Strip Length inch	1-7/16

Conductor Related

Conductor Size	275,000 - 211,500 cmils
Conductor Type	<ul style="list-style-type: none">• CU C Solid-Size• CU C Str-Size

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	100
Minimum Pack Quantity	100
Pallet Quantity	23200

Product Assets

[Customer Notices - Prop 65 Notice](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YSM292-SPEC-EN | REV 8/2023