




## YSM4C, Uninsulated Parallel Splice For 26,813 - 42,613 cmils

By Burndy  
Catalog # YSM4C

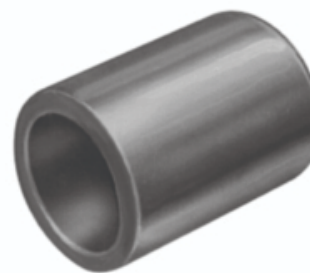

Copper Compression Parallel Splice, 26813-42613 Circular Mil,  
0.5" Splice Length, Short Barrel, Tin Plated.

### Features

- Seamless tubing
- Beveled barrel for ease of wire entry
- Tin plated
- Parallel design results in only one crimp necessary
- Uninsulated barrel provides an economical termination solution when insulation is not specified

### Application

HYLINK Type YSM seamless parallel splice connector permits wires to be laid parallel inside the connector and spliced together with the BURNDY family of HYTOOL installation tooling

### General

Catalog Number	YSM4C
Color Code	Gray
Connector Type	Parallel Splice
Die Index	8
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Material	Copper
Plated	Y
Plating Type	Tin
Sub Brand	HYLINK
Temperature Rating	90
Trade Name	HYLINK™
Type	YSM
UPC	781810805770
UPC 12 Digit	7818108057700

### Dimensions

Dimension - Length Overall inch	0.50 in
Dimension - Outside Diameter inch	0.38 in
Dimension - Strip Length inch	9/16

### Conductor Related

Conductor - Copper Solid Size	12 AWG;11 AWG;10 AWG
Conductor - Copper Solid Size Range	12 AWG-10 AWG
Conductor - Copper Str Size	12 AWG;10 AWG
Conductor - Copper Str Size Range	12 AWG-10 AWG
Conductor Size	26,813 - 42,613 cmils
Conductor Type	<ul style="list-style-type: none"><li>• CU C Solid-Size</li><li>• CU C Str-Size</li></ul>

### Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	200
Minimum Pack Quantity	200

### Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Sales Drawings - 50094200](#)



A Hubbell brand