


# YSP28T, Compression Splice, 4/0 AWG Cu, Tapered End

By Burndy  
Catalog # YSP28T

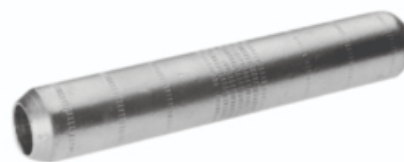

4/0 AWG CU, Tapered End, Internal Chamfer, Tin Plated,  
UL/CSA, 90°C, Up to 35kV, PURPLE Color Code, 15 Die Index.

## Application

Wire Splice

## General

Catalog Number	YSP28T
Color Code	Purple
Connector Type	LONG BARREL
Die Index	15
EU RoHS Indicator	Yes
Feature - Barrel Style	Tapered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Electro Tin plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YSP-T, High Voltage, Long Barrel
UPC	781810001301

## Dimensions

Dimension - B Length inch	1.16 in
Dimension - L Length Overall mm	62 mm
Dimension - Length Overall inch	2.45 in
Dimension - Strip Length inch	1-3/16 in

## Electrical Ratings

Voltage Rating	35 kV
----------------	-------

## Conductor Related

Conductor - Copper Str Size	4/0 AWG
Conductor - Copper Str Size Range	4/0 AWG
Conductor - Material	COPPER
Conductor Size	4/0 AWG
Conductor Type	CODE
Wire Size	#4/0 AWG

## Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

## Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	19200

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - sc20445-01](#)
- [Specifications - YSP28T](#)