




# Compression Splice

By Burndy  
Catalog # YSP29T

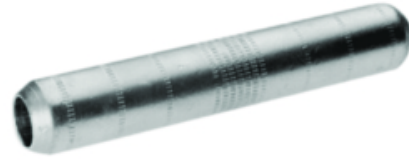

250 kcmil CU, Tapered End, Internal Chamfer, Tin Plated,  
UL/CSA, 90°C, Up to 35kV, YELLOW Color Code, 16 Die Index.

### Application

Wire Splice

### General

Color Code	Yellow
Connector Type	LONG BARREL
Die Index	16
EU RoHS Indicator	Yes
Feature - Barrel Style	Tapered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Electro Tin plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YSP-T, High Voltage, Long Barrel
UPC	781810001318

### Dimensions

Dimension - B Length inch	1.24 in
Dimension - L Length Overall mm	66 mm
Dimension - Length Overall inch	2.61 in
Dimension - Strip Length inch	1-3/32 in

### Electrical Ratings

Voltage Rating	35 kV
----------------	-------

### Conductor Related

Conductor - Copper Str Size	250 kcmil
Conductor - Copper Str Size Range	250 kcmil
Conductor - Material	COPPER
Conductor Size	250 KCMIL
Conductor Type	CODE
Wire Size	250 kcmil

### Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	11600

### Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - sc20445-01](#)



A proud member of the Hubbell Family.