


## YSP4CT, Compression Splice, 4 AWG Cu, Tapered End

By Burndy  
Catalog # [YSP4CT](#)

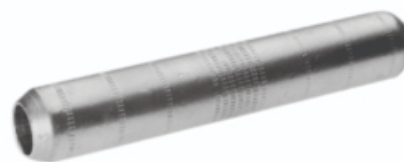

4 AWG CU, Tapered End, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, GRAY Color Code, 8 or 346 Die Index.

### Application

Wire Splice

### General

Catalog Number	YSP4CT
Color Code	Gray
Connector Type	LONG BARREL
Die Index	8
EU RoHS Indicator	Yes
Feature - Barrel Style	Tapered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Electro Tin plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YSP-T, High Voltage, Long Barrel
UPC	781810001288

### Dimensions

Dimension - B Length inch	0.93 in
Dimension - L Length Overall mm	51 mm
Dimension - Length Overall inch	1.99 in
Dimension - Strip Length inch	15/16 in

### Electrical Ratings

Voltage Rating	35 kV
----------------	-------

### Conductor Related

Conductor - Copper Str Size	4 AWG
Conductor - Copper Str Size Range	4 AWG
Conductor - Material	COPPER
Conductor Size	4 AWG
Conductor Type	CODE
Wire Size	#4 AWG

### Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

### Logistics

Carton Quantity	100
Minimum Pack Quantity	100
Pallet Quantity	76800

### Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Catalogs - BURNDY Master Catalog - Section C - Compression Connections](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Sales Drawings - sc20445-01](#)  
[Specifications - YSP4CT](#)