




## YST3030, Compresson T-Connector, 300 kcmil Cu, Standard Barrel, Tapered Ends

By Burndy  
Catalog # [YST3030](#)

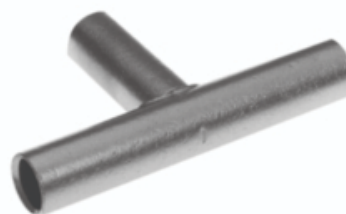

UNINSULATED HIGH VOLTAGE COPPER COMPRESSION SPLICE  
STANDARD BARREL-TAPERED ENDS.

### Application

T-Connector

### General

|                       |                      |
|-----------------------|----------------------|
| Catalog Number        | YST3030              |
| Color Code - Side A   | White                |
| Color Code - Side B   | White                |
| Connector Type        | T-COUPLER            |
| Die Index             | 17/17                |
| Die Index Run Side    | 17                   |
| Die Index Tap Side    | 17                   |
| Feature - Barrel Type | Long                 |
| Finish Type           | Tin-Plated           |
| Material              | COPPER               |
| Plated                | Y                    |
| Plating Type          | Tin - Electro Plated |
| Temperature Rating    | 194                  |
| Trade Name            | HYLINK™              |
| UPC                   | 781810502044         |
| UPC 12 Digit          | 7818105020444        |

### Dimensions

|                                     |         |
|-------------------------------------|---------|
| Dimension - A Outside Diameter inch | 0.81 in |
| Dimension - B Length fraction       | 2 in    |
| Dimension - B Length inch           | 2.00 in |
| Dimension - B Outside Diameter inch | 0.81 in |
| Dimension - L Length Overall mm     | 138 mm  |
| Dimension - Length Overall inch     | 5.44 in |
| Dimension - Width inch              | 2.25 in |

### Electrical Ratings

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 35000 |
| Voltage Rating    | 35 kV |

### Conductor Related

|                                  |                     |
|----------------------------------|---------------------|
| Conductor - Copper Str Run       | 300 KCMIL           |
| Conductor - Copper Str Run Range | 300 kcmil           |
| Conductor - Copper Str Tap       | 300 KCMIL           |
| Conductor - Copper Str Tap Range | 300 kcmil           |
| Conductor - Material             | COPPER              |
| Conductor Size                   | 300 KCMIL-300 KCMIL |
| Conductor Type                   | CODE                |

### Certifications And Compliance

|                                    |              |
|------------------------------------|--------------|
| Certification - CSA Approved       | No           |
| Certification - ETL                | No           |
| Certification - UL Recognized      | No           |
| Certification - cULus              | No           |
| Industry Standard(s)               | UL 486A-486B |
| Standards - Industry Standards Met | UL 486A-486B |
| Standards - RoHS Compliance Status | CM           |
| UL Listed                          | Yes          |

### Logistics

|                       |      |
|-----------------------|------|
| Carton Quantity       | 25   |
| Minimum Pack Quantity | 25   |
| Pallet Quantity       | 3600 |

### Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_YST\\_LineArt](#)  
[Sales Drawings - 2388612](#)  
[Specifications - YST3030](#)



A Hubbell brand