


C5, Bronze Ground Clamp, Cable to Water Pipe

By Burndy
Catalog # [C5](#)

Bronze Ground Clamp, 10-2 AWG, 1/2"-1" Water Pipe.

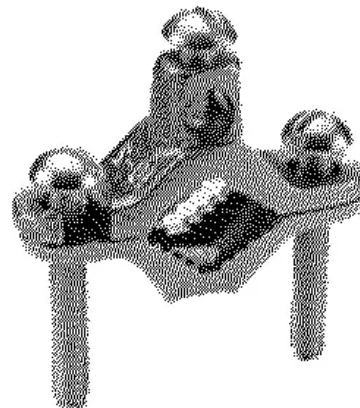

Features

- Connects grounding conductor to water pipe or copper tube
- Supplied with Zinc-plated steel hardware

Application

For Bare Wire, Connecting Grounding Conductor To Water Pipe Or Copper Tube

General

Catalog Number	C5
EU RoHS Indicator	Yes
Material	Bronze Alloy
Material - Hardware	DURIUM™ Silicon Bronze
Plated	N
Plating Type	Unplated
Sub Brand	C DIE
Type	Junior
UPC	781810142295
UPC 14 Digit GTIN	00781810142295

Dimensions

Dimension - Height inch	1.56 in
Dimension - Height mm	39.6 mm
Dimension - Hole Size inch	0.31 in
Dimension - Hole Size mm	8 mm
Dimension - L Length Overall mm	57 mm
Dimension - Length Overall inch	2.25 in
Dimension - Pad Width inch	0.50 in
Dimension - Width inch	0.56 in
Dimension - Width mm	14 mm

Conductor Related

Conductor - Armored Cable Size	N
Conductor - Copper Solid Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3

Conductor - Copper Solid Size Range	AWG;2 AWG 10 AWG-2 AWG
Conductor - Copper Str Size Range	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Size Range	10 AWG - 2 AWG
Conductor - Pipe EMT Size Range	1/2 in;3/4 in;1 in
Conductor - Pipe EMT Size Range	1/2 in-1 in

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Product Assets

[3D Models - C5_MODEL-IGES](#)
[3D Models - C5_MODEL-STEP](#)
[3D Models - C5_MODEL-PDF](#)
[Catalogs - Burndy Grounding Catalog](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_CN_LineArt](#)
[Sales Drawings - sc210654-01](#)
[Specifications - C5 Specification Sheet French](#)
[Specifications - C5 Specification Sheet English](#)