


C7, Cast Bronze Clamp, Cable to Water Pipe

By Burndy
Catalog # C7

Cast Bronze Clamp, Armored Cable to Water Pipe, 10 AWG - 2 AWG, 1-1/4" - 2" Water Pipe.

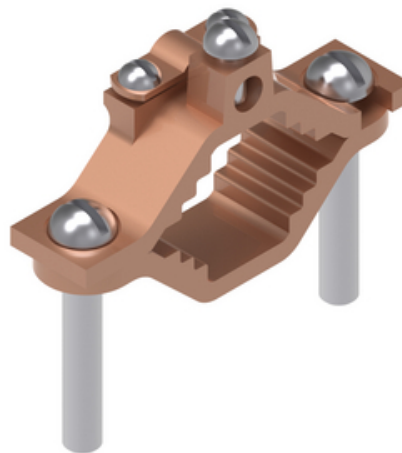

General

Application	For Connecting Armored Cable To Water Pipe And Direct Burial In Earth And Concrete
Catalog Number	C7
EU RoHS Indicator	Yes
Hardware Type	Zinc Plated
Material	Bronze Alloy
Material - Hardware Plated	Zinc Plated Steel
Plating Type	Y
Sub Brand	Zinc
Type	CLAMP
UPC	Ground Clamp
UPC 12 Digit	781810142424

Dimensions

Dimension - Height inch	2.38 in
Dimension - L Length Overall mm	92 mm
Dimension - Length Overall inch	3.62 in
Dimension - Pad Width inch	1.00 in
Dimension - Width inch	0.94 in
Dimension - Width mm	24 mm

Conductor Related

Conductor - Armored Cable Size	Y
Conductor - Copper Solid Size Range	8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Size Range	8 AWG-2 AWG
Conductor - Copper Str Size Range	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Size Range	10 AWG - 2 AWG
Conductor - Pipe EMT Size Range	1 1/4 in;1 1/2 in;2 in
Conductor - Pipe EMT Size Range	1 1/4 in-2 in
Conductor Type	CU C Str-Size
	CU C Solid-Size
	Pipe EMT-Size

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_C6_LineArt](#)
[Sales Drawings - sc210662-01](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY_CA-C7-SPEC-EN | REV 6/2024