




CCOFR, Clear Cover

By Burndy
Catalog # [CCFOFR](#)

Clear Polycarbonate H-Tap-Flame Retardant Cover, #2AWG, 600V.

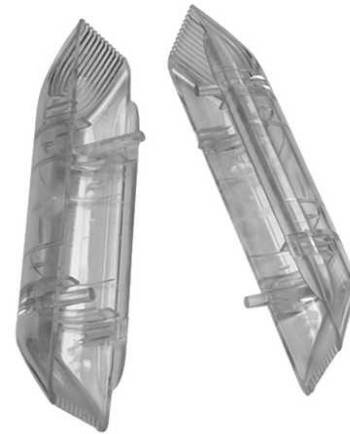

Features

- Connector end stops
- Flexible fingers
- snap tight latches
- 2piece construction
- magnifying lens

Application

Cover

General

Color	Clear
Color Code	Brown
Connector Type	H-TAP COVERS CLEAR
EU RoHS Indicator	Yes
Fire Resistance	Yes
Material	POLYCARBONATE
Operating Temperature	90 °C
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Temperature Rating	194
Type	H-Tap Connector
UPC	781810438176
UPC 12 Digit	7818104381766

Dimensions

Dimension - Height inch	1.44 in
Dimension - L Length Overall mm	112 mm
Dimension - Length Overall inch	4.42 in
Dimension - Width inch	1.21 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	600 V

Conductor Related

Conductor - AL Str Size	2 AWG
Conductor - Copper Str Compact Size	2 AWG
Conductor - Copper Str Size	2 AWG
Conductor - Copper Str Size Range	#2 AWG
Conductor - Material	COPPER
Conductor - Max Length	0.80 in
Conductor Type	CODE/FLEX
Wire Size	2 AWG

Certifications and Compliance

Certification - 94V0 Rated	Y
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	25
Pallet Quantity	2250

Product Assets

- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Sales Drawings - 10064550](#)



A proud member of the Hubbell Family.

