




CT120400D, Cable Tie, 120 Lb Tensile, Natural

By Burndy
Catalog # [CT120400D](#)

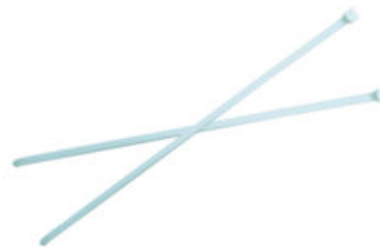

Nylon UNIRAP - 120 Lb. Tensile Strength.

General

Catalog Number	CT120400D
Color	Natural
Material	NYLON 6/6
Military Specification	MS3367
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	120
Trade Name	UNIRAP™
UPC	781810333273

Dimensions

Dimension - Bundle Diameter Max inch	4
Dimension - L Length Overall mm	383 mm
Dimension - Length Overall inch	15.09 in
Dimension - Width inch	0.3 in
Dimension - Width mm	8 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-3-9
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	2000
Packaging Type	Bag

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
[Sales Drawings - 50080813](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY_CA-CT120400D-SPEC-EN | REV 6/2024