




# KS17NK, Split Bolt Connector, Run: #8 Str-#6 Sol, Tap: #14-#6 Str, Nickel Plated

By Burndy  
Catalog # [KS17NK](#)

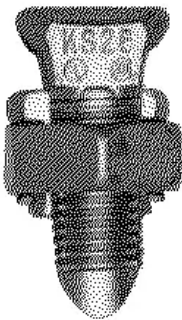

Cu Alloy SERVIT Split Bolt, #8 Str. - #6 Sol.(Run), #14 - #6 Str. (Tap), Nickel Plated.

### Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

### General

Catalog Number	KS17NK
Connector Type	Split Bolt
Material	Copper
Plated	Y
Plating Type	Nickel
Trade Name	SERVIT®
UPC	781810089323
UPC 14 Digit GTIN	00781810089323

### Dimensions

Dimension - Length Overall	1.14
inch	
Width	0.45 in

### Conductor Related

Conductor - Copper Solid Run	6 AWG
Conductor - Copper Solid Tap	6 AWG
Conductor - Copper Str Run	8 STR - 6 STR
Range	
Conductor - Copper Str Tap	8 STR - 6 STR
Range	

### Conductor Type

- CU C Solid-Run
- CU C Str-Run
- CU Weld C Str-Run
- CU C Solid-Tap
- CU C Str-Tap
- CU Weld C Str-Tap

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL486D
Standards - Industry Standards	UL486D
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	No

### Logistics

Carton Quantity	100
Pallet Quantity	9900

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - sd078561](#)
- [Specifications - KS17NK Specification Sheet English](#)
- [Specifications - KS17NK Specification Sheet French](#)