



SC2/0, Split Bolt Cover Kit

By Burndy
Catalog # [SC2/0](#)

Plastic Split Bolt Cover,Conductor range for equal Run/Tap: 4 str.-1/0 Str.

Features

- Type SC, SERVIT® Covers ar applicable for indoor or outdoor use
- Compact, 1-piece cover saves time and material by eliminating costly taping of split-bolts
- Positive latch snaps quickly over connector and is idea for tight quarters
- Self-positioning plastic fingers wrap around wires


Application

For Used In Indoors Or Outdoors Applications, KS25, KSA2

General

Catalog Number	SC2/0
Connector Type	Split Bolt
EU RoHS Indicator	Yes
Material	Plastic
Sub Brand	SERVIT COVER
Temperature Rating	194
Trade Name	SERVIT®
Type	SC
UPC	781810042250
UPC 14 Digit GTIN	00781810042250

Dimensions

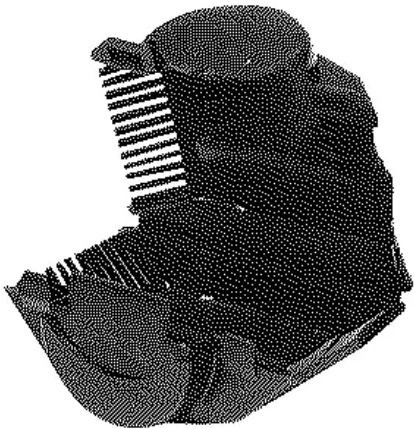

Dimension - Height mm0 mm

Conductor Related

Conductor Size4-1/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards	UL 486A-486B
Met	
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Product Assets

[Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_G1FSC_LineArt](#)
[Sales Drawings - 55878](#)
[Specifications - Burndy_SC20_Specsheet](#)
[Specifications - SC2/0 Specification Sheet French](#)
[Specifications - SC20 Specification Sheet English](#)