




# VG3, Copper Alloy Vise Connector, #2-#6 Sol

By Burndy  
Catalog # [VG3](#)

Cu Alloy Vise Connectors, #2 - #6 Sol.

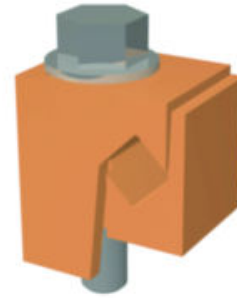

## Application

Accommodates a wide range of conductors

## General

Catalog Number	VG3
Connector Type	Stud Connector
Construction Material - Main	Copper
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Plating Type	Unplated
Trade Name	WISEIT™
Type	VG
UPC	781810475133

## Dimensions

Bolt Size	9/16 in
Dimension - B Length fraction	39/47 in
Dimension - B Length inch	0.83 in
Dimension - Pad Width inch	0.94 in
Dimension - Pin Diameter fraction	49/50 in
Dimension - Pin Diameter inch	0.98 in

## Conductor Related

Conductor - Copper Solid Run	6 - 2
Conductor - Copper Solid Run Range	6 - 2
Conductor - Copper Solid Size	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Solid Size Range	6 AWG-2 AWG
Conductor - Copper Solid Tap	6 - 2
Conductor - Copper Solid Tap Range	6 - 2
Conductor - Copper Str Run	6 - 2
Conductor - Copper Str Run Range	6 - 2
Conductor - Copper Str Tap	6 - 2
Conductor - Copper Str Tap Range	6 - 2

## Certifications And Compliance

Standards - RoHS Compliance Status	CM
------------------------------------	----

## Logistics

Carton Quantity	250
-----------------	-----

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section H - Overhead Distribution](#)  
[Customer Notices - Prop 65 Notice](#)  
[Product Cross Section Image\(s\) - BUR\\_VG\\_LineArt](#)  
[Sales Drawings - 10090832](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY\_CA-VG3-SPEC-EN | REV 6/2024