


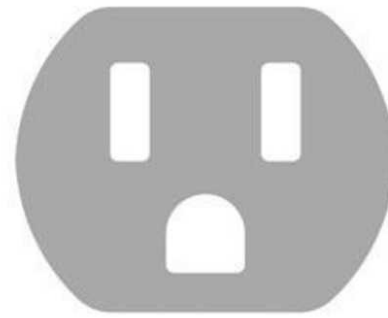

Compression Terminal

By Burndy
Catalog # YA1CA9

UNINSULATED ALUMINUM COMPRESSION TERMINAL, 2-HOLE DESIGNUL Listed 90° C600 Volts to 35 KV.



Oh No!
IMAGE COMING SOON

Application

Wire Termination

General

Color Code	Green
Connector Type	DUAL RATED
Die Index	471
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	ALUMINUM
Number of Holes	2
Physical Attribute - Number of Holes	2
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Temperature Rating	194
Trade Name	HYLUG™
UPC	621945447479
UPC 12 Digit	6219454474799

Dimensions

Dimension - Bolt Size fraction	1/2
Dimension - Bolt Size inch	0.5
Dimension - Hole Size fraction	1/2
Dimension - Hole Size inch	0.56
Dimension - Hole Size mm	14 mm
Dimension - Stud Size fraction	1/2
Physical Attribute - Tongue Angle	Straight

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - AL Str Size	1 AWG
Conductor - AL Str Size Range	1 AWG
Conductor - Copper Str Size	1 AWG
Conductor - Copper Str Size Range	1 AWG
Conductor - Material	ALUMINUM / COPPER
Conductor Size	1 AWG
Conductor Type	CODE
Wire Size	1 AWG

Certifications And Compliance

Certification - CSA Approved	Yes
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	10
Pallet Quantity	9600

Product Assets

- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - Aluminum Installation Instructions](#)
- [Sales Drawings - SD073935-01](#)



A proud member of the Hubbell Family.