




YA39A3, Al Compression, 1-Hole, 5/8" Stud, AL9CU, 750 kcmil

By Burndy
Catalog # [YA39A3](#)

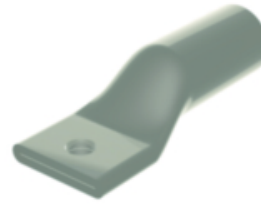

AL Terminal, AL9CU, Internal Chamfer, Tin Plated, Prefilled
PENETROX™ A13, End Cap, UL/CSA, 90°C, Up to 35kV, Color
Code, Die Index.

Application

Wire Termination

General

Catalog Number	YA39A3
Color Code	Yellow
Connector Type	DUAL RATED
Die Index	936
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	ALUMINUM
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Temperature Rating	194
Trade Name	HYLUG™
Type	YA-A, Dual Rated
UPC	781810752067
UPC 12 Digit	7818107520677

Dimensions

Dimension - B Length fraction	2-7/16 in
Dimension - B Length inch	2.46 in
Dimension - Bolt Hole Size inch	0.66 in
Dimension - Bolt Size fraction	5/8
Dimension - Bolt Size inch	0.63
Dimension - D inch	1.88 in
Dimension - Hole Size fraction	5/8
Dimension - Hole Size inch	0.69
Dimension - Hole Size mm	17.5 mm
Dimension - L Length Overall mm	147 mm
Dimension - Length Overall inch	5.80 in
Dimension - N inch	0.88 in
Dimension - Outside Diameter inch	1.46 in
Dimension - Pad Width inch	2.05 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - AL Str Size	700 KCMIL-750 KCMIL
Conductor - AL Str Size Range	700 kcmil - 750 kcmil
Conductor - Copper Str Size	700 KCMIL;750 KCMIL
Conductor - Copper Str Size Range	700 kcmil - 750 kcmil
Conductor - Material	ALUMINUM / COPPER
Conductor Size	700 KCMIL;750 KCMIL
Conductor Type	CODE
Wire Size	700 KCMIL;750 KCMIL

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry	UL 486A-486B
Standards Met	
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	3
-----------------	---

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Installation Manuals - Aluminum Installation Instructions](#)
[Sales Drawings - SD073935-01](#)

Dimension - Strip Length inch	2 7/8
Dimension - Stud Size fraction	5/8
Dimension - Stud Size inch	5/8
Dimension - Thread Size	5/8 in
Dimension - Z (inch)	1.00 in
Physical Attribute - Tongue Angle	Straight



A proud member of the Hubbell Family.