




YCS28R, Aluminum Sleeve, Staked Cable Stop

By Burndy
Catalog # [YCS28R](#)

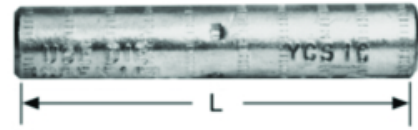

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses. ANSI C119.4 CLASS 2 (PARTIAL TENSION), Index: 249.

Application

For ACSR, All Aluminum, 6201, 5005 And Compressed Conductors

General

Catalog Number	YCS28R
Connector Type	Splice
Die Index	249
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYSPLICE
Trade Name	HYSPLICE™
Type	YCS-R
UPC	781810820544
UPC 12 Digit	7818108205444

Dimensions

Dimension - B Length inch	2.81 in
Dimension - L Length Overall mm	146 mm
Dimension - Length Overall inch	5.75 in
Dimension - Outside Diameter inch	0.87 in

Conductor Related

Conductor - ACSR Str Size	4/O (6/1) Penquin AWG
Conductor - AL Str Size	4/O AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	RUS
Standards - Industry Standards Met	RUS
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	25
Pallet Quantity	7400

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section H - Overhead Distribution](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YCS-R_LineArt](#)
[Sales Drawings - 50115707](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_CA-YCS28R-SPEC-EN | REV 6/2024