


Bare Ferrule For 10 AWG

By Burndy
Catalog # YF1010UIL

Wire ferrules are also known as cord end terminals or bootlace ferrules. These are electrical connectors used to terminate stranded wires. Uninsulated ferrules are designed to form neat end terminations to multi-strand cables or wires.

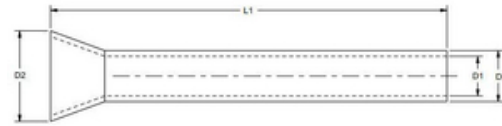

Features

- Made of electrolytic copper, tin plated
- Seamless barrels
- Smooth funnel entry to make wire insertion easier
- UL listed per UL486F requirements
- RoHS Compliant

Application

For Use On Copper Conductor

General

Catalog Number	YF1010UIL
Connector Type	End Termination
EU RoHS Indicator	Yes
Insulation	N
Material	Copper
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	FERRULES
Type	Bootlace Ferrule
UPC	621945623262

Dimensions

Dimension - D inch	0.15 in
Dimension - D1 inch	0.14 in
Dimension - D2 inch	0.19 in
Dimension - Length Overall inch	0.39 in

Conductor Related

Conductor - Copper Solid Size	10 AWG
Conductor - Copper Str Size	10 AWG
Conductor Size	10 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	250
Minimum Pack Quantity	250

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section B - Small Compression](#)
[Sales Drawings - 50111874](#)