




YGHHC34C26 Compression Grounding C-TAP Connector

By Burndy
Catalog # [YGHHC34C26](#)

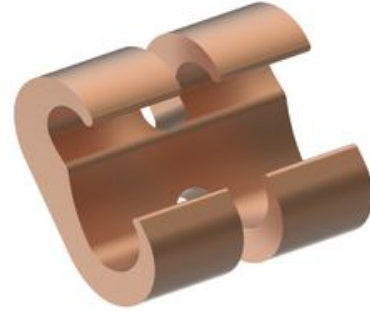

Compression ground connector, Material: Copper, Range Run: 300 Kcmil-500 Kcmil or 3/4" Rod, Tap: 6 SOL-2/0 STR.

Application

Cable to Cable or Cable to Ground Rod Applications

General

Catalog Number	YGHHC34C26
Connector Type	Tap
Construction Material - Main	Copper
Die Index	1011
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Trade Name	HYTAP™
Type	Taps
UPC	621945456259
UPC 12 Digit	6219454562599

Dimensions

Width	2.13 in
-------	---------

Conductor Related

Conductor - Copper Solid Tap Range	6 Solid - 2/0 Solid
Conductor - Copper Str Run Range	300 - 500 kcmil
Conductor - Copper Str Tap Range	6 Stranded - 2/0 Stranded
Conductor - Rod Run Range	3/4" Rod

Certifications And Compliance

Certification - CSA Approved	[Delete]
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	<ul style="list-style-type: none">UL 467IEEE 837IEEE 837 2014 QualifiedUL 486A-486B
Standards - Industry Standards Met	UL467;IEEE 837;IEEE 837 2014 Qualified;UL 486A-486B
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	20
Pallet Quantity	2400

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section E1 - Compression Grounding](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50064429](#)



A proud member of the Hubbell Family.