


Compression H-Tap

By Burndy
Catalog # [YH4434](#)

Cu H-Tap Connector, 1000-750 kcmil, 777-750 kcmil Flex, 500-350 Kcmil, 350 kcmil Flex, Tin plated.

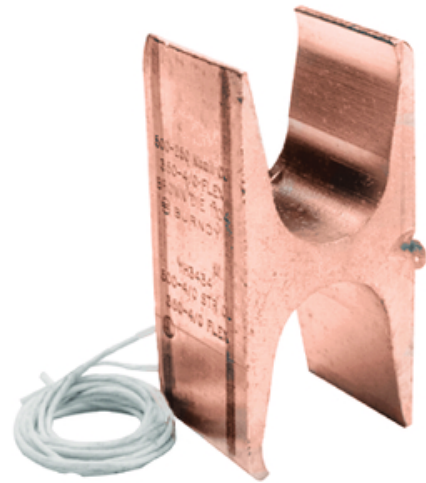

Application

Wire Tap

General

Catalog Number	YH4434
Color Code	Yellow
Connector Type	H-TAP
Die Index	KR
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Temperature Rating	194
Trade Name	CRIMPIT™
Type	Compression Taps
UPC	781810418949
UPC 12 Digit	7818104189499

Dimensions

Dimension - Height inch	3.38 in
Dimension - L Length Overall mm	25 mm
Dimension - Length Overall inch	1.00 in
Dimension - Strip Length inch	1-3/8
Dimension - Width fraction	1.70 in
Dimension - Width inch	3.50 in

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Flex G Run	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex G Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex G Tap	350 kcmil
Conductor - Copper Flex G Tap Range	350 kcmil
Conductor - Copper Flex H Run	700 kcmil
Conductor - Copper Flex H Run Range	700 kcmil
Conductor - Copper Flex H Tap	350 kcmil
Conductor - Copper Flex H Tap Range	350 kcmil
Conductor - Copper Flex I Run	750 KCMIL-500 KCMIL
Conductor - Copper Flex I Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex I Tap	350 kcmil
Conductor - Copper Flex I Tap Range	350 KCMIL
Conductor - Copper Flex K Run	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex K Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex K Tap	350 kcmil
Conductor - Copper Flex K Tap Range	350 kcmil
Conductor - Copper Flex M Run	500 kcmil;600 kcmil;700 kcmil
Conductor - Copper Flex M Run Range	500 kcmil-700 kcmil
Conductor - Copper Flex M Tap	350 kcmil
Conductor - Copper Flex M Tap Range	350 kcmil
Conductor - Copper Str Run	700 kcmil;750 kcmil;800 kcmil;850 kcmil;900 kcmil;1000 kcmil
Conductor - Copper Str Run Range	1000 KCMIL-750 KCMIL
Conductor - Copper Str Tap	350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Tap Range	500 KCMIL-350 KCMIL

Conductor - Material COPPER
Conductor Type CODE/FLEX

Certifications And Compliance

Certification - CSA Approved Yes
Industry Standard(s) UL 486A-486B
Standards - Industry UL467
Standards Met
Standards - RoHS Compliance CM
Status
UL Listed Yes

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD..206566-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_CA-YH4434-SPEC-EN | REV 6/2024