


YHR950, Line Tap for Cu, AL, ACSR, Compact

By Burndy
Catalog # [YHR950](#)

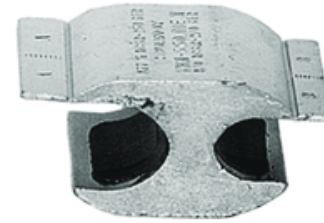

Compression Line Tap for Copper, AL or ACSR and Compact Conductors, groove A(Run) ACSR:556.5 (18/1) - 954 (45/7).

Application

For Copper, Aluminum Or ACSR And Compact Conductors

General

Catalog Number	YHR950
Construction Material - Main	Aluminum
Die Index	KR
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYCRIMP
Trade Name	HYCRIMP™
Type	YHR
UPC	781810139905

Dimensions

Dimension - Height fraction	3-7/50 in
Dimension - Height inch	3.14 in
Dimension - L Length Overall mm	152 mm
Dimension - Length Overall inch	6.00 in
Dimension - Width fraction	1-33/50 in
Dimension - Width inch	1.66 in
Dimension - Width mm	42 mm

Conductor Related

Conductor - ACSR Str Run	336.4 (24/7) Parakeet kcmil;556.5 (26/7) Dove kcmil;556.5 (30/7) Eagle kcmil;605 (24/7) Peacock kcmil;605 (26/7) Squab kcmil;605 (30/19) Teal kcmil;636 (24/7) Rook kcmil;636 (26/7) Grosbeak kcmil;636 (30/19) Egret kcmil;666.6 (24/7) Flamingo kcmil;715.5 (54/7) Crow kcmil;715.5 (24/7) Stilt kcmil;715.5 (26/7) Starling kcmil;715.5 (30/19) Redwing kcmil;795 (54/7) Condor kcmil;795 (26/7) Drake kcmil;795 (30/19) Mallard kcmil;874.5 54/7 Condor kcmil;900 (54/7) Canary
--------------------------	---

Conductor - ACSR Str Tap Range	336.4 (18/1) Merlin kcmil-954 (45/7) Rail kcmil
Conductor - AL Str Run	336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil;636 kcmil;650 kcmil;700 kcmil;715 kcmil;750 kcmil;795 kcmil;800 kcmil;874 kcmil;900 kcmil;954 kcmil;1000 kcmil
Conductor - AL Str Run Range	336 kcmil-1000 kcmil
Conductor - AL Str Tap	336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil;636 kcmil;650 kcmil;700 kcmil;715 kcmil;750 kcmil;795 kcmil;800 kcmil;874 kcmil;900 kcmil;954 kcmil;1000 kcmil
Conductor - AL Str Tap Range	336 kcmil-1000 kcmil
Conductor - Copper Str Run	350 kcmil;400 kcmil;450 kcmil;500 kcmil;550 kcmil;600 kcmil;700 kcmil;750 kcmil;800 kcmil;850 kcmil;900 kcmil;1000 kcmil
Conductor - Copper Str Run Range	350 kcmil-1000 kcmil
Conductor - Copper Str Tap	350 kcmil;400 kcmil;450 kcmil;500 kcmil;550 kcmil;600 kcmil;700 kcmil;750 kcmil;800 kcmil;850 kcmil;900 kcmil;1000 kcmil
Conductor - Copper Str Tap Range	350 kcmil-1000 kcmil

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM

Conductor - ACSR Str Run Range	kcmil;954 (45/7) Rail kcmil-954 (45/7) Rail kcmil
Conductor - ACSR Str Tap	336.4 (18/1) Merlin kcmil;336.4 (26/7) Linnet kcmil;336.4 (30/7) Oriole kcmil;397.5 (18/1) Chickadee kcmil;397.5 (24/7) Brant kcmil;397.5 (26/7) Ibis kcmil;397.5 (30/7) Larkspur kcmil;477.0 (18/1) Pelican kcmil;477.0 (24/7) Flicker kcmil;477.0 (26/7) Hawk kcmil;477. (30/7) Hen kcmil;500.0 (30/7) Heron kcmil;556.5 (24/7) Parakeet kcmil;556.5 (26/7) Dove kcmil;556.5 (30/7) Eagle kcmil;605 (24/7) Peacock kcmil;605 (26/7) Squab kcmil;605 (30/19) Teal kcmil;636 (24/7) Rook kcmil;636 (26/7) Grosbeak kcmil;636 (30/19) Egret kcmil;666.6 (24/7) Flamingo kcmil;715.5 (54/7) Crow kcmil;715.5 (24/7) Stilt

Product Assets

[3D Models - YHR950_MODEL-IGES](#)
[3D Models - YHR950_MODEL-STEP](#)
[3D Models - YHR950_MODEL-PDF](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section H - Overhead Distribution](#)
[Product Cross Section Image\(s\) - BUR_YH_LINEART](#)
[Sales Drawings - SD..073376-01](#)



A proud member of the Hubbell Family.